

## ★ NK24/20-XL

Needle roller bearing


Schaeffler ID:  
0507540760000

Needle roller bearings NK, light series

★ Preferred product

X-life

### Technical information

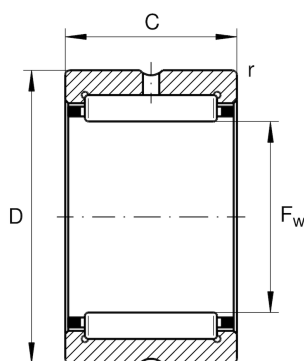

#### Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,04 kg	Weight

#### Main Dimensions & Performance Data

$F_w$	24 mm	Under roller diameter
$D$	32 mm	Outside diameter
$C$	20 mm	Width, outer ring
$C_r$	21.400 N	Basic dynamic load rating, radial
$C_{0r}$	30.500 N	Basic static load rating, radial
$C_{ur}$	5.400 N	Fatigue load limit, radial
$n_G$	18.500 1/min	Limiting speed
$n_{gr}$	10.700 1/min	Reference speed

#### Dimensions

$r_{\min}$	0,3 mm	Minimum chamfer dimension
------------	--------	---------------------------

#### Additional information

	G24X32X4	Sealing ring
--	----------	--------------