

★ NKI15/20-XL

Needle roller bearing



Schaeffler ID:
0507619780000

Needle roller bearings NKI, light series

★ Preferred product

X-life

Technical information

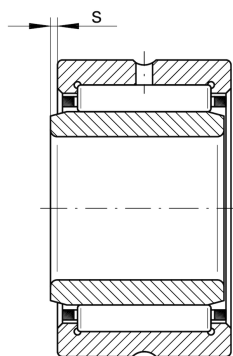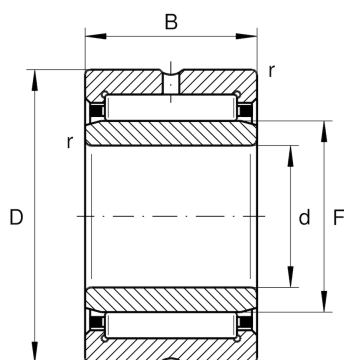

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	49,4 g	Weight

Main Dimensions & Performance Data

d	15 mm	Bore diameter
D	27 mm	Outside diameter
B	20 mm	Width
C_r	18.700 N	Basic dynamic load rating, radial
C_{0r}	23.600 N	Basic static load rating, radial
C_{ur}	4.200 N	Fatigue load limit, radial
n_G	21.600 1/min	Limiting speed
n_{gr}	12.100 1/min	Reference speed

Dimensions

F	19 mm	Raceway diameter inner ring
r_{\min}	0,3 mm	Minimum chamfer dimension
s	0,5 mm	Axial displacement