

★ NA4834-XL

Needle roller bearing



Schaeffler ID:
0507685220000

Needle roller bearing NA..-XL, single row,
with inner ring, outer ring with 2 bords

★ Preferred product

X-life

Technical information

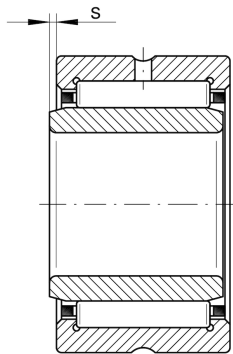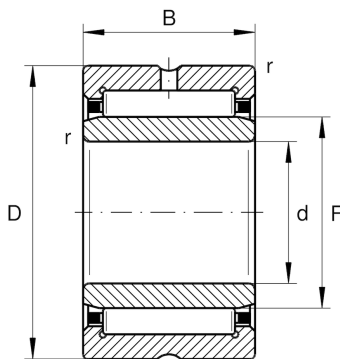

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	3,936 kg	Weight

Main Dimensions & Performance Data

d	170 mm	Bore diameter
D	215 mm	Outside diameter
B	45 mm	Width
C_r	209.000 N	Basic dynamic load rating, radial
C_{0r}	510.000 N	Basic static load rating, radial
C_{ur}	76.000 N	Fatigue load limit, radial
n_G	2.550 1/min	Limiting speed
n_{gr}	1.610 1/min	Reference speed

Dimensions

F	185 mm	Raceway diameter inner ring
r_{\min}	1,1 mm	Minimum chamfer dimension
s	1,5 mm	Axial displacement