

★ NA4907-2RSR-XL

Needle roller bearing


Schaeffler ID:
0507752350000

Needle roller bearings NA49...-2RSR,
dimension series 49, lip seals on both
sides

★ Preferred product

X-life

Technical information

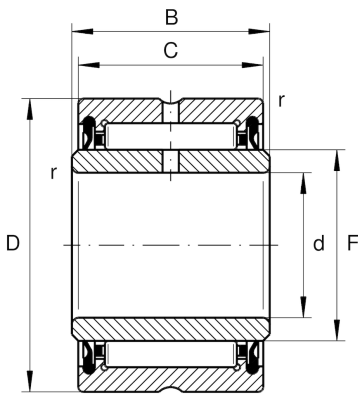

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	100 °C	Operating temperature max.
	0,178 kg	Weight

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D	55 mm	Outside diameter
B	21 mm	Width, inner ring
C_r	29.500 N	Basic dynamic load rating, radial
C_{0r}	39.500 N	Basic static load rating, radial
C_{ur}	7.400 N	Fatigue load limit, radial
$n_{G \text{ Grease}}$	6.400 1/min	Limiting speed for grease lubrication

Dimensions

F	42 mm	Raceway diameter inner ring
C	20 mm	Width, outer ring
r_{\min}	0,6 mm	Minimum chamfer dimension