

RNAO25X35X17-XL




Needle roller bearing

Schaeffler ID:
0507759100000

Needle roller bearings RNAO, without ribs

X-life

Technical information

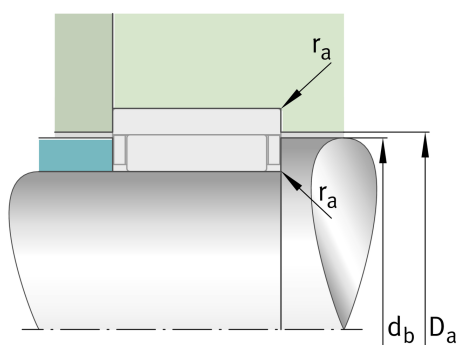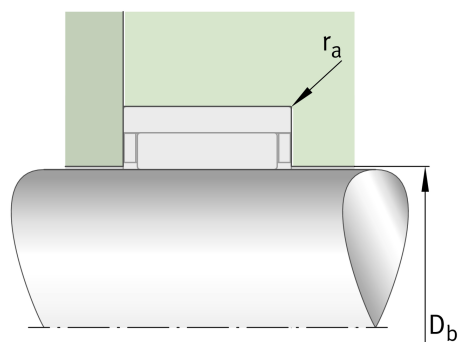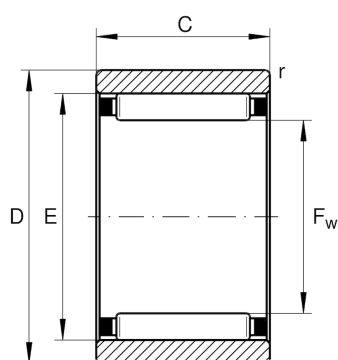

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	53 g	Weight

Main Dimensions & Performance Data

F_w	25 mm	Under roller diameter
D	35 mm	Outside diameter
C	17 mm	Width, outer ring
C_r	16.800 N	Basic dynamic load rating, radial
C_{0r}	26.000 N	Basic static load rating, radial
C_{ur}	4.300 N	Fatigue load limit, radial
n_G	18.100 1/min	Limiting speed
n_{gr}	11.000 1/min	Reference speed

Dimensions

E	29 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension

Mounting dimensions

D_b	25,6 mm	Shoulder diameter axial guidance NK/housing
d_b	28,4 mm	Shoulder diameter axial guidance NK/shaft
D_a	29,5 mm	Shoulder diameter outer ring
$r_{a max}$	0,3 mm	Maximum recess radius