




LR203-2RSR

Track roller

Schaeffler ID:
0922432070000

Track roller LR..-2RSR, single row, no
plastic tyre

Technical information

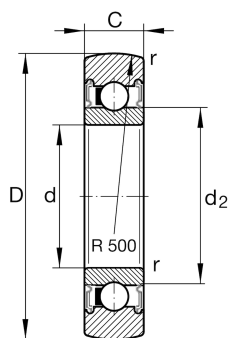

Main Dimensions & Performance Data

D	47 mm	Outside diameter
d	17 mm	Bore diameter
C	12 mm	Height
$C_{r w}$	8.900 N	Basic dynamic load rating, radial
$C_{0r w}$	4.550 N	Basic static load rating, radial
$C_{ur w}$	229 N	Fatigue load limit, radial
n_{DG}	9.000 1/min	Speed on permanent grease lubrication
	0,108 kg	Weight

Dimensions

d_2	24 mm	Diameter of thrust washer
r_{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile