

★ KWVE25-B-SNL


Recirculating ball bearing carriage

Schaeffler ID:
0127395610240

Carriages KWVE...-B-SNL, narrow, low,
long carriage, four-row


★ Preferred product

Technical information

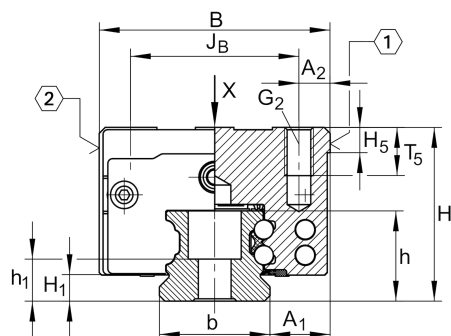

Main Dimensions & Performance Data

H	31 mm	height system
B	48 mm	width carriage
L	109,1 mm	overall length carriage
C	23.400 N	dynamic load rating
C ₀	54.000 N	static load rating
M _{0x}	745 Nm	static moment rating about X axis
M _{0y}	825 Nm	static moment rating about Y axis
M _{0z}	825 Nm	static moment rating about Z axis
	0,708 kg	Weight

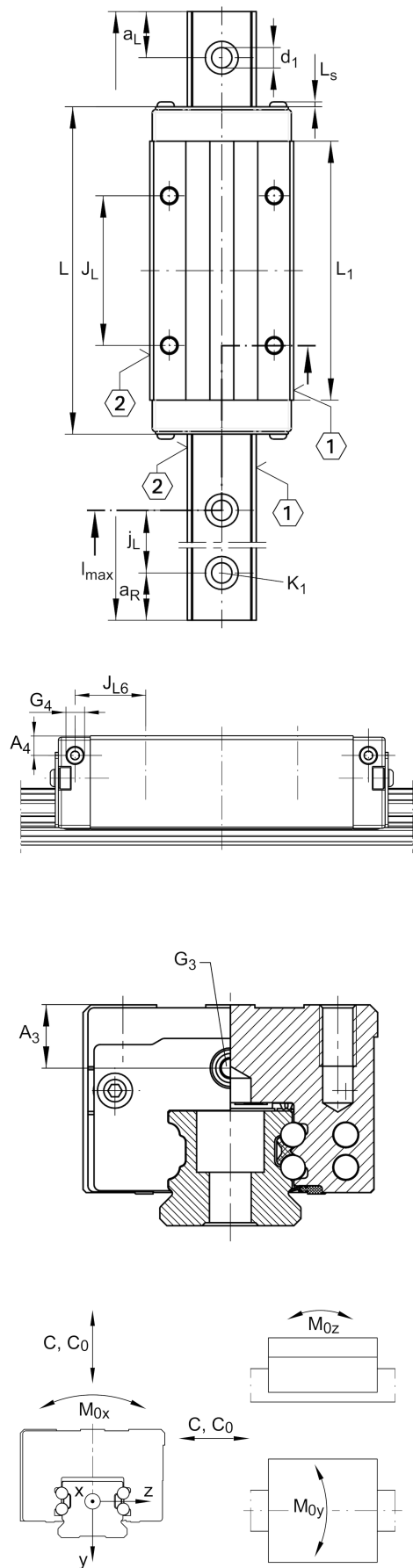

Mounting dimensions

VMKB_065	KWVE	Material name
A ₁	12,5 mm	
J _B	35 mm	
b	23 mm	width rail
A ₂	6,5 mm	
L ₁	86,5 mm	
L _S	1,65 mm	
J _L	50 mm	
H ₁	5,1 mm	
H ₅	5,25 mm	
T ₅	7,5 mm	
G ₂	M6	fixing screws below (DIN ISO 4762-12.9)
G _{2 M_A}	17 Nm	maximum tightening torque
A ₃	6 mm	position lubrication connector
G ₃	M6	lubrication connector
t _{G₃}	7 mm	maximum permissible screw depth for lubrication connectors
A ₄	4 mm	position lubrication connector
G ₄	M3 mm	lubrication connector
t _{G₄}	6 mm	maximum permissible screw depth for lubrication connectors
J _{L6}	22,5 mm	position lubrication connector

