



## ★ K4X7X7-TV



### Needle roller cage assembly

Schaeffler ID:  
0000111696063

Needle roller cage assembly K...-TV, single  
row

★ Preferred product

## Technical information

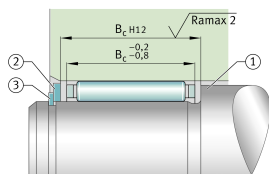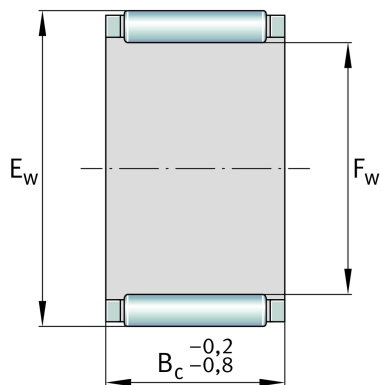

### Temperature range

$T_{min}$	-20 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.
	0,48 g	Weight

### Main Dimensions & Performance Data

$F_w$	4 mm	Inner diameter of needle roller complement
$E_w$	7 mm	Outside diameter of needle roller complement
$B_c$	7 mm	Width
$C_r$	1.740 N	Basic dynamic load rating, radial
$C_{0r}$	1.270 N	Basic static load rating, radial
$C_{ur}$	148 N	Fatigue load limit, radial
$n_G$	42.500 1/min	Limiting speed
$n_{gr}$	59.000 1/min	Reference speed