

★ K110X118X30



Needle roller cage assembly

Schaeffler ID:
0000170436063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

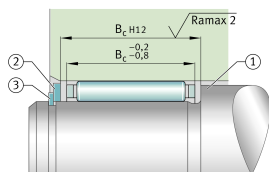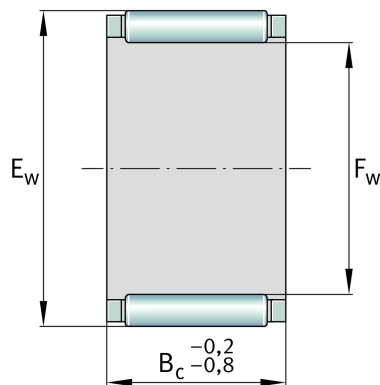

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	0,229 kg	Weight

Main Dimensions & Performance Data

F_w	110 mm	Inner diameter of needle roller complement
E_w	118 mm	Outside diameter of needle roller complement
B_c	30 mm	Width
C_r	78.000 N	Basic dynamic load rating, radial
C_{0r}	219.000 N	Basic static load rating, radial
C_{ur}	30.000 N	Fatigue load limit, radial
n_G	4.300 1/min	Limiting speed
n_{gr}	2.750 1/min	Reference speed