

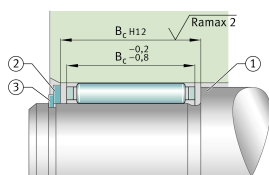
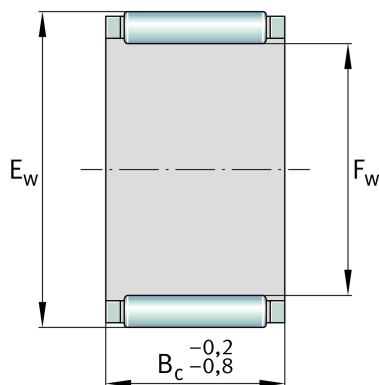
**K160X170X46**

Needle roller cage assembly

Schaeffler ID:
0000174266063

Needle roller cage assembly K, single row

Technical information

**Temperature range**

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	140 °C	Operating temperature max.
	0,598 kg	Weight

Main Dimensions & Performance Data

F_w	160 mm	Inner diameter of needle roller complement
E_w	170 mm	Outside diameter of needle roller complement
B_c	46 mm	Width
C_r	152.000 N	Basic dynamic load rating, radial
C_{0r}	510.000 N	Basic static load rating, radial
C_{ur}	64.000 N	Fatigue load limit, radial
n_G	2.950 1/min	Limiting speed
n_{gr}	1.970 1/min	Reference speed