



★ K195X205X37


Needle roller cage assembly

Schaeffler ID:
0000175826063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

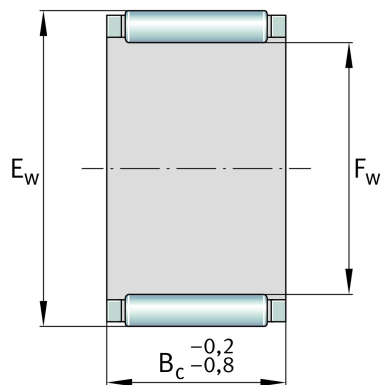

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	0,62 kg	Weight

Main Dimensions & Performance Data

F_w	195 mm	Inner diameter of needle roller complement
E_w	205 mm	Outside diameter of needle roller complement
B_c	37 mm	Width
C_r	133.000 N	Basic dynamic load rating, radial
C_{0r}	450.000 N	Basic static load rating, radial
C_{ur}	52.000 N	Fatigue load limit, radial
n_G	2.450 1/min	Limiting speed
n_{gr}	1.760 1/min	Reference speed