



## ★ LR25X30X16,5


Inner ring

Schaeffler ID:  
0000216100000

Inner ring LR, cylindrical

★ Preferred product

### Technical information

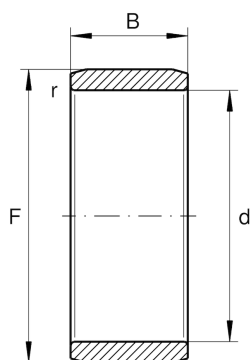

#### Main Dimensions & Performance Data

d	25 mm	Bore diameter
F	30 mm	Raceway diameter inner ring
B	16,5 mm	Width
r <sub>min</sub>	0,3 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	27,04 g	Weight