



★ K10X13X13-TV



Needle roller cage assembly

Schaeffler ID:
0000240746063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

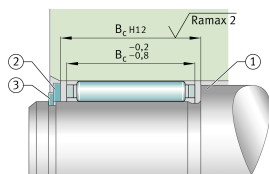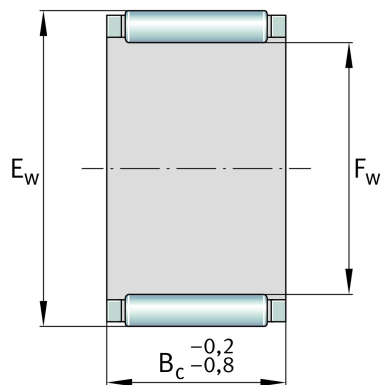

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	2,22 g	Weight

Main Dimensions & Performance Data

F_w	10 mm	Inner diameter of needle roller complement
E_w	13 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	6.200 N	Basic dynamic load rating, radial
C_{0r}	7.800 N	Basic static load rating, radial
C_{ur}	1.080 N	Fatigue load limit, radial
n_G	29.500 1/min	Limiting speed
n_{gr}	24.400 1/min	Reference speed