

★ K7X10X10-TV



Needle roller cage assembly

Schaeffler ID:
0000241716063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

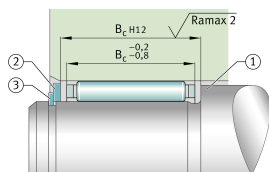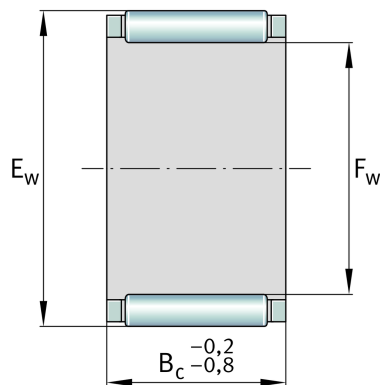

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	1,2 g	Weight

Main Dimensions & Performance Data

F_w	7 mm	Inner diameter of needle roller complement
E_w	10 mm	Outside diameter of needle roller complement
B_c	10 mm	Width
C_r	3.650 N	Basic dynamic load rating, radial
C_{0r}	3.600 N	Basic static load rating, radial
C_{ur}	495 N	Fatigue load limit, radial
n_G	34.500 1/min	Limiting speed
n_{gr}	35.000 1/min	Reference speed