



★ K14X18X13


Needle roller cage assembly

Schaeffler ID:
0000504316063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

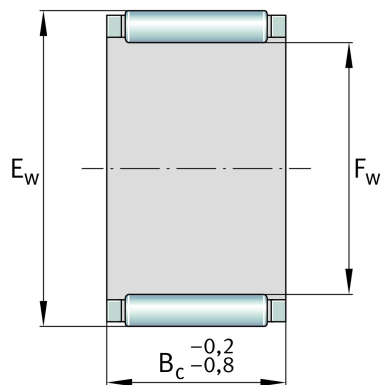

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	140 °C	Operating temperature max.
	6,7 g	Weight

Main Dimensions & Performance Data

F_w	14 mm	Inner diameter of needle roller complement
E_w	18 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	8.200 N	Basic dynamic load rating, radial
C_{0r}	10.100 N	Basic static load rating, radial
C_{ur}	1.340 N	Fatigue load limit, radial
n_G	25.000 1/min	Limiting speed
n_{gr}	17.700 1/min	Reference speed