



★ LR25X30X38,5


Inner ring

Schaeffler ID:
0000597810000

Inner ring LR, cylindrical

★ Preferred product

Technical information

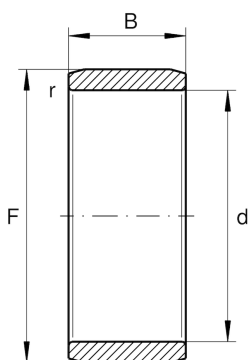

Main Dimensions & Performance Data

d	25 mm	Bore diameter
F	30 mm	Raceway diameter inner ring
B	38,5 mm	Width
r _{min}	0,3 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	64,3 g	Weight