



★ K15X21X21


Needle roller cage assembly

Schaeffler ID:
0000719866063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

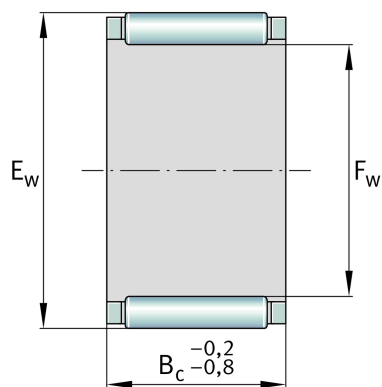

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	16,01 g	Weight

Main Dimensions & Performance Data

F_w	15 mm	Inner diameter of needle roller complement
E_w	21 mm	Outside diameter of needle roller complement
B_c	21 mm	Width
C_r	19.400 N	Basic dynamic load rating, radial
C_{0r}	24.300 N	Basic static load rating, radial
C_{ur}	3.350 N	Fatigue load limit, radial
n_G	23.600 1/min	Limiting speed
n_{gr}	14.400 1/min	Reference speed