



## ★ K35X40X13



### Needle roller cage assembly

Schaeffler ID:  
0000842986063

Needle roller cage assembly K, single row

★ Preferred product

## Technical information

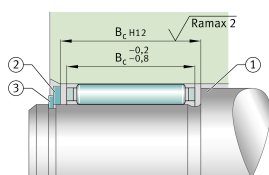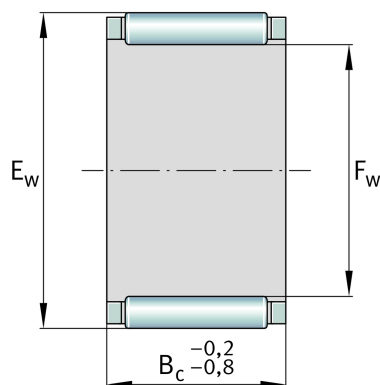

### Temperature range

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	140 °C	Operating temperature max.
	16,17 g	Weight

### Main Dimensions & Performance Data

$F_w$	35 mm	Inner diameter of needle roller complement
$E_w$	40 mm	Outside diameter of needle roller complement
$B_c$	13 mm	Width
$C_r$	17.100 N	Basic dynamic load rating, radial
$C_{0r}$	30.000 N	Basic static load rating, radial
$C_{ur}$	3.950 N	Fatigue load limit, radial
$n_G$	13.100 1/min	Limiting speed
$n_{gr}$	7.300 1/min	Reference speed