



★ K35X40X27-TV


Needle roller cage assembly

Schaeffler ID:
0000886506063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

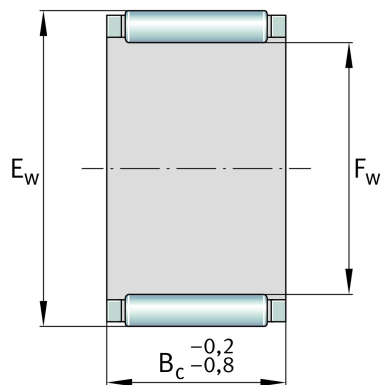

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	22,5 g	Weight

Main Dimensions & Performance Data

F_w	35 mm	Inner diameter of needle roller complement
E_w	40 mm	Outside diameter of needle roller complement
B_c	27 mm	Width
C_r	25.000 N	Basic dynamic load rating, radial
C_{0r}	48.500 N	Basic static load rating, radial
C_{ur}	6.800 N	Fatigue load limit, radial
n_G	13.100 1/min	Limiting speed
n_{gr}	7.900 1/min	Reference speed