

★ K20X26X13


Needle roller cage assembly

Schaeffler ID:
0001303386063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

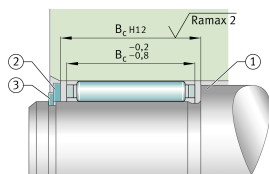

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	12,2 g	Weight

Main Dimensions & Performance Data

F_w	20 mm	Inner diameter of needle roller complement
E_w	26 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	14.400 N	Basic dynamic load rating, radial
C_{0r}	17.900 N	Basic static load rating, radial
C_{ur}	2.380 N	Fatigue load limit, radial
n_G	20.900 1/min	Limiting speed
n_{gr}	11.600 1/min	Reference speed