

## ★ K26X30X22-ZW



### Needle roller cage assembly

Schaeffler ID:  
0001386656063

Needle roller cage assembly K...ZW, two-row

★ Preferred product

## Technical information

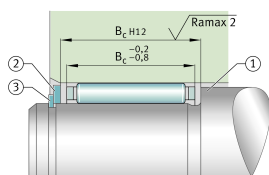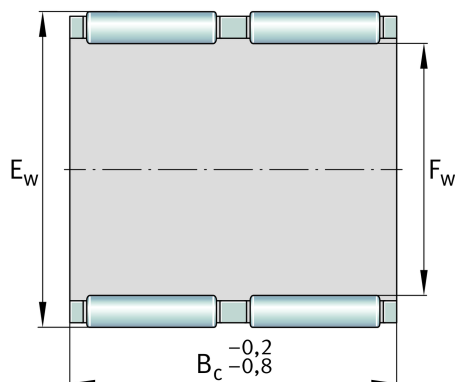

### Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	140 °C	Operating temperature max.
	19,6 g	Weight

### Main Dimensions & Performance Data

$F_w$	26 mm	Inner diameter of needle roller complement
$E_w$	30 mm	Outside diameter of needle roller complement
$B_c$	22 mm	Width
$C_r$	15.700 N	Basic dynamic load rating, radial
$C_{0r}$	28.500 N	Basic static load rating, radial
$C_{ur}$	3.600 N	Fatigue load limit, radial
$n_G$	17.500 1/min	Limiting speed
$n_{gr}$	10.400 1/min	Reference speed