



★ K21X25X13


Needle roller cage assembly

Schaeffler ID:
0001762306063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

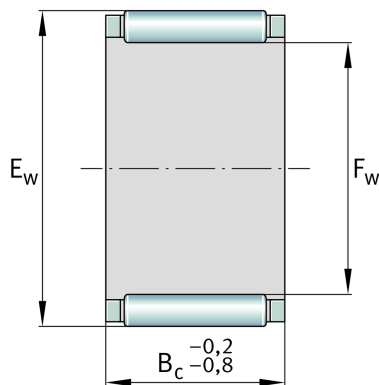

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	9,7 g	Weight

Main Dimensions & Performance Data

F_w	21 mm	Inner diameter of needle roller complement
E_w	25 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	10.100 N	Basic dynamic load rating, radial
C_{0r}	15.100 N	Basic static load rating, radial
C_{ur}	2.010 N	Fatigue load limit, radial
n_G	20.900 1/min	Limiting speed
n_{gr}	12.300 1/min	Reference speed