

★ K25X29X13



Needle roller cage assembly

Schaeffler ID:
0001762656063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

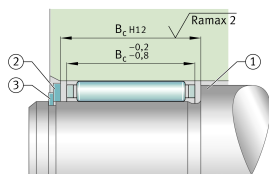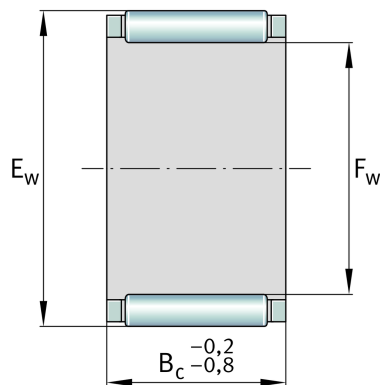

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	11,36 g	Weight

Main Dimensions & Performance Data

F_w	25 mm	Inner diameter of needle roller complement
E_w	29 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	11.300 N	Basic dynamic load rating, radial
C_{0r}	18.400 N	Basic static load rating, radial
C_{ur}	2.440 N	Fatigue load limit, radial
n_G	18.100 1/min	Limiting speed
n_{gr}	10.400 1/min	Reference speed