



★ K24X28X17


Needle roller cage assembly

Schaeffler ID:
0001822816063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

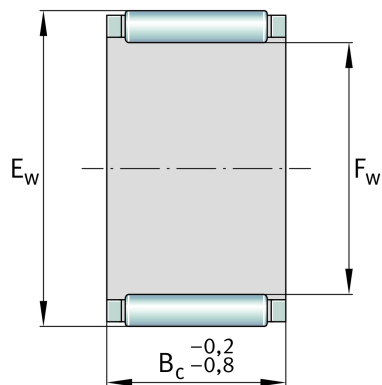

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	14 g	Weight

Main Dimensions & Performance Data

F_w	24 mm	Inner diameter of needle roller complement
E_w	28 mm	Outside diameter of needle roller complement
B_c	17 mm	Width
C_r	14.500 N	Basic dynamic load rating, radial
C_{0r}	25.000 N	Basic static load rating, radial
C_{ur}	3.350 N	Fatigue load limit, radial
n_G	18.800 1/min	Limiting speed
n_{gr}	10.600 1/min	Reference speed