



★ K20X24X17



Needle roller cage assembly

Schaeffler ID:
0001823466063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

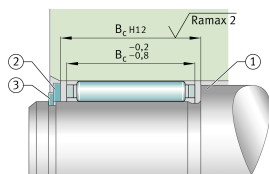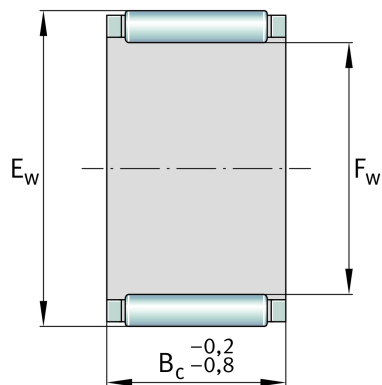

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	11,5 g	Weight

Main Dimensions & Performance Data

F_w	20 mm	Inner diameter of needle roller complement
E_w	24 mm	Outside diameter of needle roller complement
B_c	17 mm	Width
C_r	12.900 N	Basic dynamic load rating, radial
C_{0r}	20.400 N	Basic static load rating, radial
C_{ur}	2.700 N	Fatigue load limit, radial
n_G	21.300 1/min	Limiting speed
n_{gr}	12.500 1/min	Reference speed