

## ★ K16X20X17



### Needle roller cage assembly

Schaeffler ID:  
0001926196063

Needle roller cage assembly K, single row

★ Preferred product

## Technical information

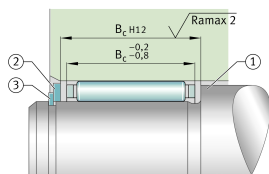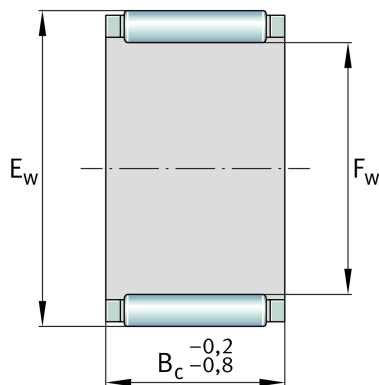

### Temperature range

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	140 °C	Operating temperature max.
	0,009 kg	Weight

### Main Dimensions & Performance Data

$F_w$	16 mm	Inner diameter of needle roller complement
$E_w$	20 mm	Outside diameter of needle roller complement
$B_c$	17 mm	Width
$C_r$	11.700 N	Basic dynamic load rating, radial
$C_{0r}$	16.800 N	Basic static load rating, radial
$C_{ur}$	2.230 N	Fatigue load limit, radial
$n_G$	23.600 1/min	Limiting speed
$n_{gr}$	15.200 1/min	Reference speed