



★ K20X28X25


Needle roller cage assembly

Schaeffler ID:
0001979126063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

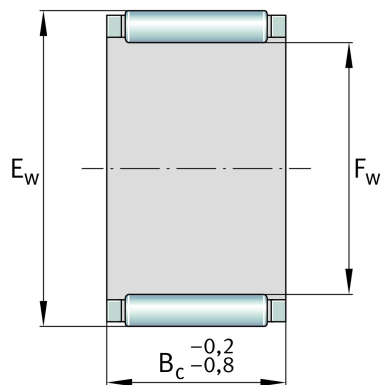

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	32,74 g	Weight

Main Dimensions & Performance Data

F_w	20 mm	Inner diameter of needle roller complement
E_w	28 mm	Outside diameter of needle roller complement
B_c	25 mm	Width
C_r	30.500 N	Basic dynamic load rating, radial
C_{0r}	39.000 N	Basic static load rating, radial
C_{ur}	5.400 N	Fatigue load limit, radial
n_G	20.400 1/min	Limiting speed
n_{gr}	10.800 1/min	Reference speed