



★ K16X22X12


Needle roller cage assembly

Schaeffler ID:
0001981536063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

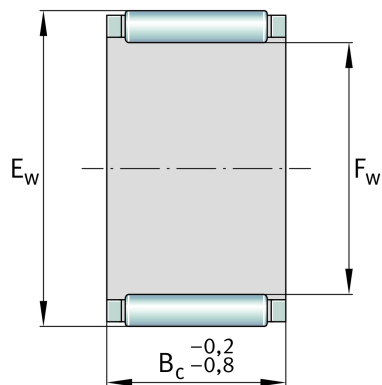

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	9 g	Weight

Main Dimensions & Performance Data

F_w	16 mm	Inner diameter of needle roller complement
E_w	22 mm	Outside diameter of needle roller complement
B_c	12 mm	Width
C_r	11.500 N	Basic dynamic load rating, radial
C_{0r}	12.500 N	Basic static load rating, radial
C_{ur}	1.810 N	Fatigue load limit, radial
n_G	22.900 1/min	Limiting speed
n_{gr}	14.300 1/min	Reference speed