



★ K12X15X13-TV


Needle roller cage assembly

Schaeffler ID:
0002431676063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

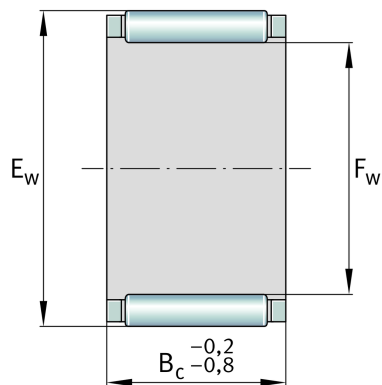

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	2,43 g	Weight

Main Dimensions & Performance Data

F_w	12 mm	Inner diameter of needle roller complement
E_w	15 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	6.400 N	Basic dynamic load rating, radial
C_{0r}	8.500 N	Basic static load rating, radial
C_{ur}	1.190 N	Fatigue load limit, radial
n_G	27.000 1/min	Limiting speed
n_{gr}	21.100 1/min	Reference speed