



★ K25X31X21


Needle roller cage assembly

Schaeffler ID:
0002641136063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

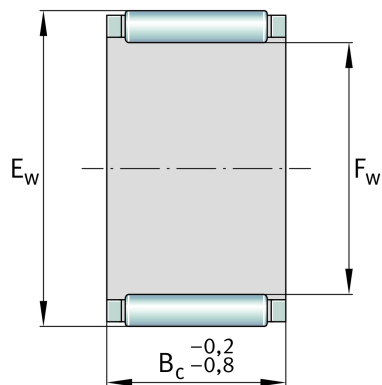

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	24,1 g	Weight

Main Dimensions & Performance Data

F_w	25 mm	Inner diameter of needle roller complement
E_w	31 mm	Outside diameter of needle roller complement
B_c	21 mm	Width
C_r	24.700 N	Basic dynamic load rating, radial
C_{0r}	38.000 N	Basic static load rating, radial
C_{ur}	5.200 N	Fatigue load limit, radial
n_G	17.500 1/min	Limiting speed
n_{gr}	9.400 1/min	Reference speed