



★ K16X24X20


Needle roller cage assembly

Schaeffler ID:
0002696896063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

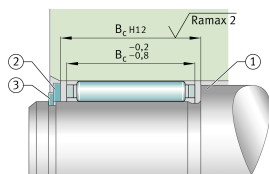

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	140 °C	Operating temperature max.
	21,76 g	Weight

Main Dimensions & Performance Data

F_w	16 mm	Inner diameter of needle roller complement
E_w	24 mm	Outside diameter of needle roller complement
B_c	20 mm	Width
C_r	21.400 N	Basic dynamic load rating, radial
C_{0r}	23.500 N	Basic static load rating, radial
C_{ur}	3.000 N	Fatigue load limit, radial
n_G	22.400 1/min	Limiting speed
n_{gr}	13.200 1/min	Reference speed