



★ K17X21X10



Needle roller cage assembly

Schaeffler ID:
0002849046063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

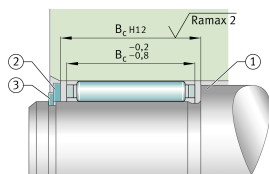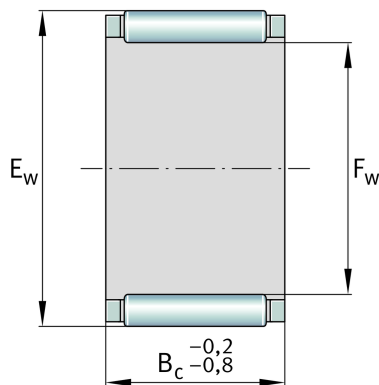

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	4,8 g	Weight

Main Dimensions & Performance Data

F_w	17 mm	Inner diameter of needle roller complement
E_w	21 mm	Outside diameter of needle roller complement
B_c	10 mm	Width
C_r	8.100 N	Basic dynamic load rating, radial
C_{0r}	10.600 N	Basic static load rating, radial
C_{ur}	1.340 N	Fatigue load limit, radial
n_G	22.900 1/min	Limiting speed
n_{gr}	14.400 1/min	Reference speed