



★ K16X20X10


Needle roller cage assembly

Schaeffler ID:
0002849206063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

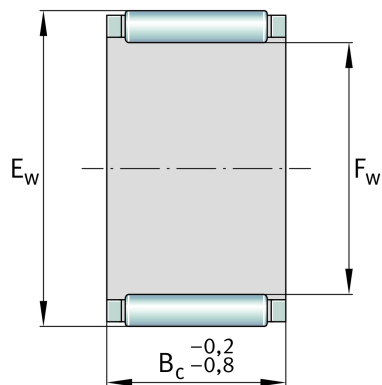

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	4,69 g	Weight

Main Dimensions & Performance Data

F_w	16 mm	Inner diameter of needle roller complement
E_w	20 mm	Outside diameter of needle roller complement
B_c	10 mm	Width
C_r	7.800 N	Basic dynamic load rating, radial
C_{0r}	9.900 N	Basic static load rating, radial
C_{ur}	1.250 N	Fatigue load limit, radial
n_G	23.600 1/min	Limiting speed
n_{gr}	15.200 1/min	Reference speed