



★ K20X30X30



Needle roller cage assembly

Schaeffler ID:
0002885196063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

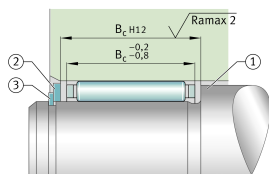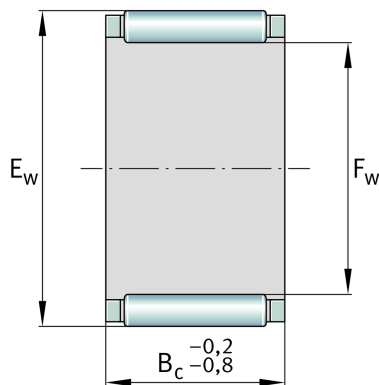

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	49,23 g	Weight

Main Dimensions & Performance Data

F_w	20 mm	Inner diameter of needle roller complement
E_w	30 mm	Outside diameter of needle roller complement
B_c	30 mm	Width
C_r	35.500 N	Basic dynamic load rating, radial
C_{0r}	41.500 N	Basic static load rating, radial
C_{ur}	5.600 N	Fatigue load limit, radial
n_G	19.600 1/min	Limiting speed
n_{gr}	10.800 1/min	Reference speed