



★ K50X58X20



Needle roller cage assembly

Schaeffler ID:
0006193536063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

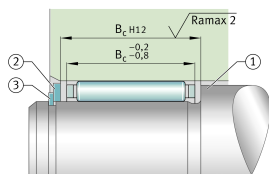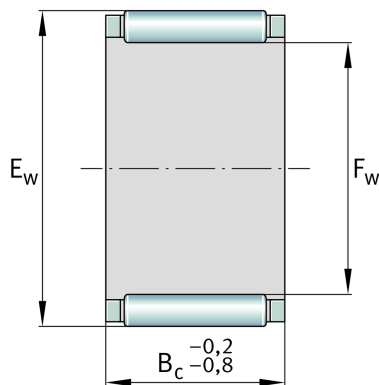

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	75,06 g	Weight

Main Dimensions & Performance Data

F_w	50 mm	Inner diameter of needle roller complement
E_w	58 mm	Outside diameter of needle roller complement
B_c	20 mm	Width
C_r	35.500 N	Basic dynamic load rating, radial
C_{0r}	62.000 N	Basic static load rating, radial
C_{ur}	8.900 N	Fatigue load limit, radial
n_G	9.100 1/min	Limiting speed
n_{gr}	5.400 1/min	Reference speed