

★ K40X45X27



Needle roller cage assembly

Schaeffler ID:
0006237846063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

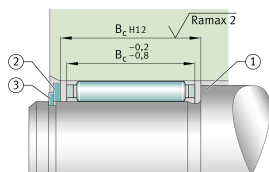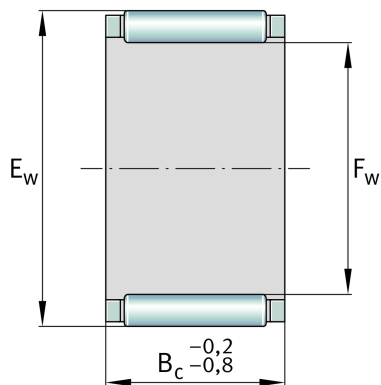

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	47,68 g	Weight

Main Dimensions & Performance Data

F_w	40 mm	Inner diameter of needle roller complement
E_w	45 mm	Outside diameter of needle roller complement
B_c	27 mm	Width
C_r	33.000 N	Basic dynamic load rating, radial
C_{0r}	73.000 N	Basic static load rating, radial
C_{ur}	10.500 N	Fatigue load limit, radial
n_G	11.500 1/min	Limiting speed
n_{gr}	6.500 1/min	Reference speed