



★ K35X42X18



Needle roller cage assembly

Schaeffler ID:
0006564966063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

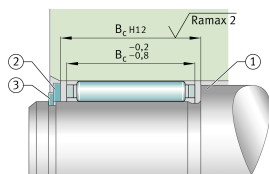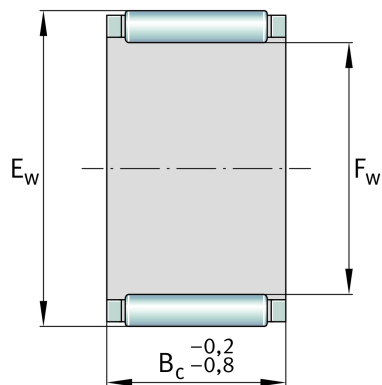

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	33,6 g	Weight

Main Dimensions & Performance Data

F_w	35 mm	Inner diameter of needle roller complement
E_w	42 mm	Outside diameter of needle roller complement
B_c	18 mm	Width
C_r	27.500 N	Basic dynamic load rating, radial
C_{0r}	43.000 N	Basic static load rating, radial
C_{ur}	6.100 N	Fatigue load limit, radial
n_G	12.700 1/min	Limiting speed
n_{gr}	7.100 1/min	Reference speed