



★ K30X37X16



Needle roller cage assembly

Schaeffler ID:
0006867946063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

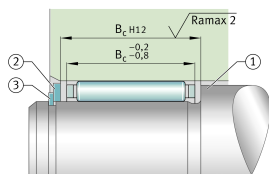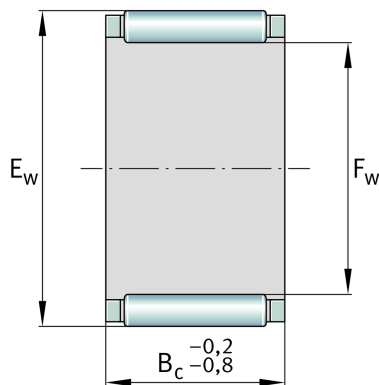

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	27,06 g	Weight

Main Dimensions & Performance Data

F_w	30 mm	Inner diameter of needle roller complement
E_w	37 mm	Outside diameter of needle roller complement
B_c	16 mm	Width
C_r	23.100 N	Basic dynamic load rating, radial
C_{0r}	33.500 N	Basic static load rating, radial
C_{ur}	4.550 N	Fatigue load limit, radial
n_G	14.600 1/min	Limiting speed
n_{gr}	8.000 1/min	Reference speed