



★ LR50X55X20,5


Inner ring

Schaeffler ID:
0007842810000

Inner ring LR, cylindrical

★ Preferred product

Technical information

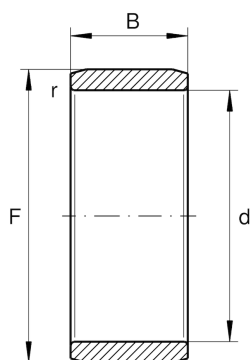

Main Dimensions & Performance Data

d	50 mm	Bore diameter
F	55 mm	Raceway diameter inner ring
B	20,5 mm	Width
r_{\min}	0,6 mm	Minimum chamfer dimension
	30 °	Chamfer angle
	65,1 g	Weight