

★ K30X35X13



Needle roller cage assembly

Schaeffler ID:
0009873876063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

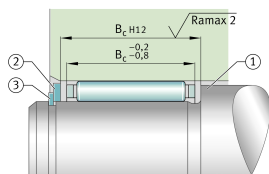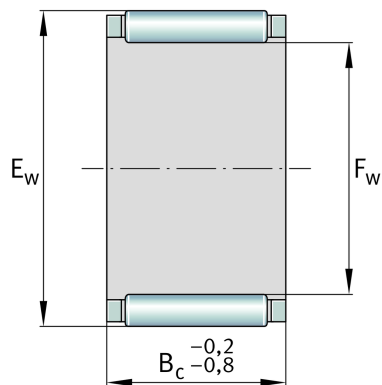

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	13,9 g	Weight

Main Dimensions & Performance Data

F_w	30 mm	Inner diameter of needle roller complement
E_w	35 mm	Outside diameter of needle roller complement
B_c	13 mm	Width
C_r	15.600 N	Basic dynamic load rating, radial
C_{0r}	25.500 N	Basic static load rating, radial
C_{ur}	3.350 N	Fatigue load limit, radial
n_G	15.100 1/min	Limiting speed
n_{gr}	8.400 1/min	Reference speed