

★ K35X45X20



Needle roller cage assembly

Schaeffler ID:
0010192286063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

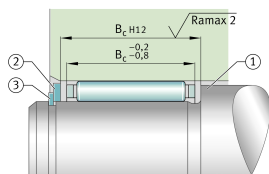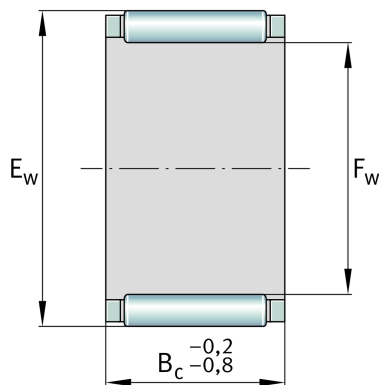

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	55,54 g	Weight

Main Dimensions & Performance Data

F_w	35 mm	Inner diameter of needle roller complement
E_w	45 mm	Outside diameter of needle roller complement
B_c	20 mm	Width
C_r	37.000 N	Basic dynamic load rating, radial
C_{0r}	50.000 N	Basic static load rating, radial
C_{ur}	6.600 N	Fatigue load limit, radial
n_G	12.300 1/min	Limiting speed
n_{gr}	6.800 1/min	Reference speed