

★ K80X88X30



Needle roller cage assembly

Schaeffler ID:
0012128346063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

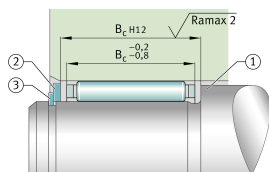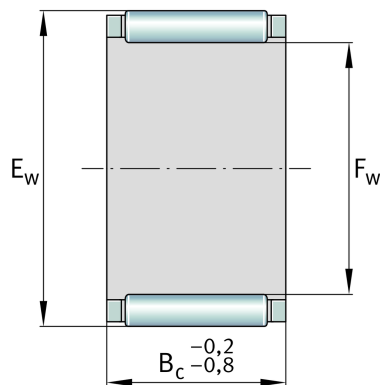

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	0,001 kg	Weight

Main Dimensions & Performance Data

F_w	80 mm	Inner diameter of needle roller complement
E_w	88 mm	Outside diameter of needle roller complement
B_c	30 mm	Width
C_r	71.000 N	Basic dynamic load rating, radial
C_{0r}	176.000 N	Basic static load rating, radial
C_{ur}	25.500 N	Fatigue load limit, radial
n_G	5.800 1/min	Limiting speed
n_{gr}	3.400 1/min	Reference speed