

★ K68X74X35-ZW



Needle roller cage assembly

Schaeffler ID:
0012236236063

Needle roller cage assembly K...-ZW, two-row

★ Preferred product

Technical information

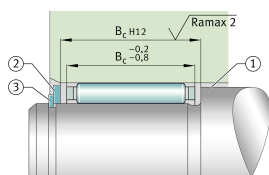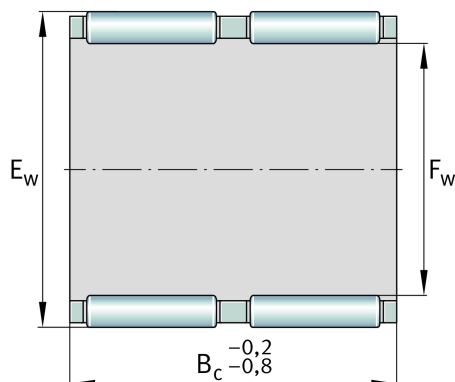

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	0,123 kg	Weight

Main Dimensions & Performance Data

F_w	68 mm	Inner diameter of needle roller complement
E_w	74 mm	Outside diameter of needle roller complement
B_c	35 mm	Width
C_r	48.500 N	Basic dynamic load rating, radial
C_{0r}	125.000 N	Basic static load rating, radial
C_{ur}	17.500 N	Fatigue load limit, radial
n_G	6.900 1/min	Limiting speed
n_{gr}	4.450 1/min	Reference speed