



★ K38X43X17


Needle roller cage assembly

Schaeffler ID:
0014113656063

Needle roller cage assembly K, single row

★ Preferred product

Technical information

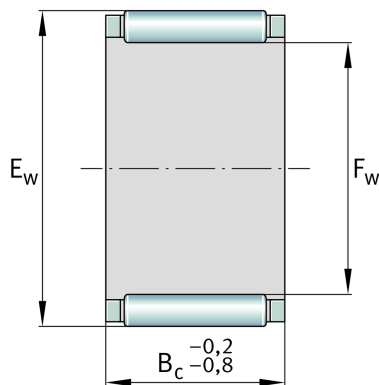

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.
	28,66 g	Weight

Main Dimensions & Performance Data

F_w	38 mm	Inner diameter of needle roller complement
E_w	43 mm	Outside diameter of needle roller complement
B_c	17 mm	Width
C_r	20.500 N	Basic dynamic load rating, radial
C_{0r}	38.500 N	Basic static load rating, radial
C_{ur}	4.950 N	Fatigue load limit, radial
n_G	12.100 1/min	Limiting speed
n_{gr}	7.000 1/min	Reference speed