



★ K14X18X15-TV


Needle roller cage assembly

Schaeffler ID:
0014751426063

Needle roller cage assembly K...TV, single row

★ Preferred product

Technical information

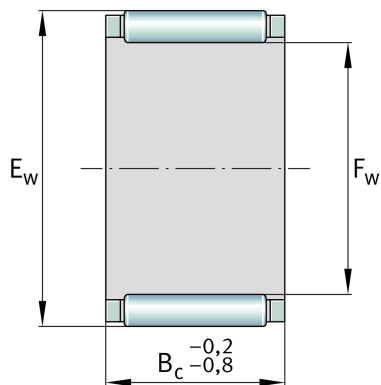

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	5 g	Weight

Main Dimensions & Performance Data

F_w	14 mm	Inner diameter of needle roller complement
E_w	18 mm	Outside diameter of needle roller complement
B_c	15 mm	Width
C_r	9.500 N	Basic dynamic load rating, radial
C_{0r}	12.300 N	Basic static load rating, radial
C_{ur}	1.570 N	Fatigue load limit, radial
n_G	25.000 1/min	Limiting speed
n_{gr}	17.400 1/min	Reference speed