



★ K15X18X17-TV


Needle roller cage assembly

Schaeffler ID:
0015304456063

Needle roller cage assembly K...-TV, single row

★ Preferred product

Technical information

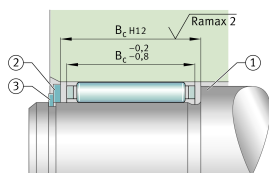

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	3,7 g	Weight

Main Dimensions & Performance Data

F_w	15 mm	Inner diameter of needle roller complement
E_w	18 mm	Outside diameter of needle roller complement
B_c	17 mm	Width
C_r	8.000 N	Basic dynamic load rating, radial
C_{0r}	12.100 N	Basic static load rating, radial
C_{ur}	1.760 N	Fatigue load limit, radial
n_G	24.600 1/min	Limiting speed
n_{gr}	17.700 1/min	Reference speed