


H35,0/30 BE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

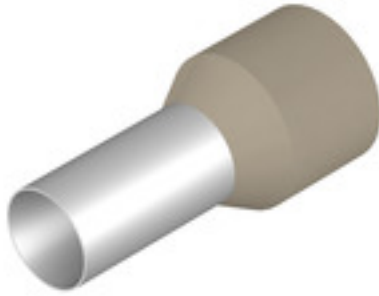

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code

General ordering data

Version	Wire-end ferrule, Standard, 19 mm, 16 mm, beige
Order No.	0317200000
Type	H35,0/30 BE
GTIN (EAN)	4008 190023904
Qty.	50 pc(s).
Packaging	loose

Creation date February 23, 2023 12:01:21 PM CET

Catalogue status 18.02.2023 / We reserve the right to make technical changes.

H35,0/30 BE

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 1.18 g

Technical data

Description of article	Wire end ferrule with plastic collar, beige	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	12.7 mm	Colour code	Weidmüller
Conductor cross-section	35 mm ²	Contact surface diameter (D1)	8.3 mm
Contact surface length (L2)	16 mm	L1 in mm	30 mm
Metal sleeve thickness (S1)	0.2 mm	Plastic collar thickness (S2)	0.4 mm
Stripping length	19 mm	Wire connection cross section AWG, max.	AWG 2

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ECLASS 9.0	27-40-02-01
ECLASS 9.1	27-40-02-01	ECLASS 10.0	27-40-02-01
ECLASS 11.0	27-40-02-01	ECLASS 12.0	27-40-02-01

Approvals

Approvals



ROHS Conform

UL File Number Search UL Website

Certificate no. (cULus) E499744

Downloads

Engineering Data [CAD data – STEP](#)

Engineering Data [WSCAD, Zuken E3.S](#)

Catalogues [Catalogues in PDF-format](#)

Brochures

Data sheet

H35,0/30 BE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

