

SH 3

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

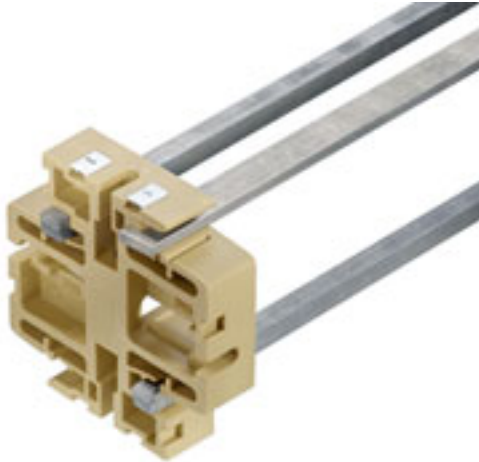

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

Version	Accessories, Rail support, Polyamide 66
Order No.	0556660000
Type	SH 3
GTIN (EAN)	4008190123086
Qty.	10 Stück

SH 3

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technische Daten

Dimensions and weights

Depth	65 mm	Depth (inches)	2.559 inch
Height	15 mm	Height (inches)	0.591 inch
Width	65 mm	Width (inches)	2.559 inch
Net weight	26.403 g		

Temperatures

Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C
----------------------------------	--------	----------------------------------	--------

Material data

Material	Polyamide 66	Surface finish	all others
Colour	silver	UL 94 flammability rating	V-2

System specifications

Version	15 x 6 mm busbar connection
---------	-----------------------------

Conductors for clamping (rated connection)

Type of connection	Miscellaneous
--------------------	---------------

General

Operating temperature range, max.	100 °C	Surface finish	all others
-----------------------------------	--------	----------------	------------

Classifications

ETIM 6.0	EC001166	ETIM 7.0	EC001166
ETIM 8.0	EC001166	ECLASS 9.0	27-40-06-07
ECLASS 9.1	27-14-11-92	ECLASS 10.0	27-40-06-07
ECLASS 11.0	27-40-06-07	ECLASS 12.0	27-40-06-07

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	EPLAN
Catalogues	Catalogues in PDF-format
Brochures	CAT 1 TERM 16/17 EN