

TNHE WSI6 60-150V DC/AC**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030


32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

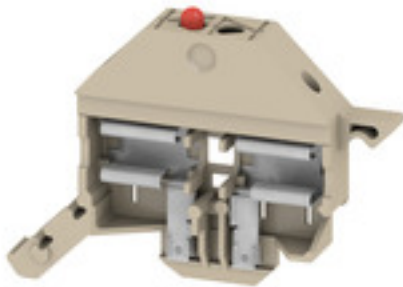

The fuse holder SIHA quickly turns a disconnect terminal into a fuse terminal: simply remove the disconnect lever and attach the fuse unit.

General ordering data

| | |
|------------|----------------------------|
| Version | W-Series, Isolating lever |
| Order No. | 1035500000 |
| Type | TNHE WSI6 60-150V DC/AC |
| GTIN (EAN) | 4008190205539 |
| Qty. | 50 pc(s). |

TNHE WSI6 60-150V DC/AC

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data

Dimensions and weights

| | | | |
|------------|----------|-----------------|------------|
| Depth | 28.8 mm | Depth (inches) | 1.134 inch |
| Height | 50.15 mm | Height (inches) | 1.974 inch |
| Width | 6.95 mm | Width (inches) | 0.274 inch |
| Net weight | 5.66 g | | |

Temperatures

| | | | |
|----------------------------------|----------------|----------------------------------|--------|
| Storage temperature | -25 °C...55 °C | Continuous operating temp., min. | -50 °C |
| Continuous operating temp., max. | 120 °C | | |

Material data

| | | | |
|---------------------------|-------|--------|------------|
| Material | Wemid | Colour | dark beige |
| UL 94 flammability rating | V-0 | | |

Additional technical data

| | | | |
|--------------------------|---------|---------------------|-----------------|
| Explosion-tested version | No | Installation advice | Direct mounting |
| Type of fixing | Snap-on | | |

Dimensions

| | |
|-----------------|--------|
| Pitch in mm (P) | 7.8 mm |
|-----------------|--------|

General

| | |
|---------------------|-----------------|
| Installation advice | Direct mounting |
|---------------------|-----------------|

Rating data

| | |
|---------------|-----|
| Rated current | 0 A |
|---------------|-----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 6.0 | EC002848 | ETIM 7.0 | EC002848 |
| ETIM 8.0 | EC002848 | ECLASS 9.0 | 27-14-11-92 |
| ECLASS 9.1 | 27-14-11-92 | ECLASS 10.0 | 27-14-11-92 |
| ECLASS 11.0 | 27-14-11-92 | ECLASS 12.0 | 27-14-11-92 |

Approvals

Approvals



| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Downloads

| | |
|------------------|--|
| Engineering Data | WSCAD |
| Catalogues | Catalogues in PDF-format |

Data sheet

TNHE WSI6 60-150V DC/AC

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Drawings

