

WBB ZA WDU1.5/BL 10/10**Weidmüller Interfaces GmbH & Co. KG**

Postfach 3030

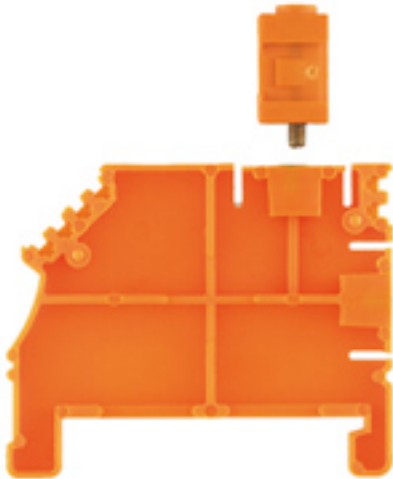
32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Product image

Fixing brackets for our pluggable terminal blocks serve as mechanical fasteners for the respective plugs. They protect both the connector and the contact from mechanical stress and unintentional loosening due to vibration.

General ordering data

Version	W-Series, Fixing bracket, orange, 5 mm
Order No.	1068260000
Type	WBB ZA WDU1.5/BL 10/10
GTIN (EAN)	4008190015657
Qty.	10 pc(s).

WBB ZA WDU1.5/BL 10/10

Weidmüller Interfaces GmbH & Co. KG

Postfach 3030

32760 Detmold

Tel. +49 5231 14-0

Fax. +49 5231 14-2083

info@weidmueller.com

www.weidmueller.com

Technical data

Dimensions and weights

Depth	36.7 mm	Depth (inches)	1.445 inch
Height	45.4 mm	Height (inches)	1.787 inch
Width	5 mm	Width (inches)	0.197 inch
Net weight	4.31 g		

Temperatures

Storage temperature	-25 °C...55 °C	Continuous operating temp., min.	-50 °C
Continuous operating temp., max.	100 °C		

Material data

Material	PA 66	Colour	orange
UL 94 flammability rating	V-2		

System specifications

Version	End and intermediate plate
---------	----------------------------

Additional technical data

Installation advice	Direct mounting	Snap-on	No
---------------------	-----------------	---------	----

General

Installation advice	Direct mounting
---------------------	-----------------

Classifications

ETIM 6.0	EC000886	ETIM 7.0	EC000886
ETIM 8.0	EC000886	ECLASS 9.0	27-14-11-92
ECLASS 9.1	27-14-11-33	ECLASS 10.0	27-14-11-92
ECLASS 11.0	27-14-11-92	ECLASS 12.0	27-14-11-92

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
SCIP	936a8f21-8ce1-4838-a60e-9ad69268c052

Approvals

ROHS	Conform
------	---------

Downloads

Engineering Data	CAD data – STEP
Engineering Data	WSCAD, Zuken E3.S
User Documentation	StorageConditionsTerminalBlocks
Catalogues	Catalogues in PDF-format
Brochures	